


MATERIAL

» Graphit Q70, Q60, Q40

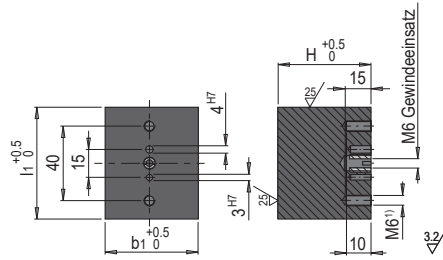

b1	l1	H	Q70	EUR	Q60	EUR	Q40	EUR
20	52	30	V 92561/20/ 52/30	< >	V 92564/20/ 52/30	< >	V 92567/20/ 52/30	< >
20	52	50	V 92561/20/ 52/50	< >	V 92564/20/ 52/50	< >	V 92567/20/ 52/50	< >
20	52	80	V 92561/20/ 52/80	< >	V 92564/20/ 52/80	< >	V 92567/20/ 52/80	< >
20	60	30	V 92561/20/ 60/30	< >	V 92564/20/ 60/30	< >	V 92567/20/ 60/30	< >
20	60	50	V 92561/20/ 60/50	< >	V 92564/20/ 60/50	< >	V 92567/20/ 60/50	< >
20	60	80	V 92561/20/ 60/80	< >	V 92564/20/ 60/80	< >	V 92567/20/ 60/80	< >
20	70	30		-	V 92564/20/ 70/30	< >	V 92567/20/ 70/30	< >
20	70	50		-	V 92564/20/ 70/50	< >	V 92567/20/ 70/50	< >
20	70	80		-	V 92564/20/ 70/80	< >		-
20	80	30		-	V 92564/20/ 80/30	< >	V 92567/20/ 80/30	< >
20	80	50		-	V 92564/20/ 80/50	< >	V 92567/20/ 80/50	< >
20	80	80		-	V 92564/20/ 80/80	< >	V 92567/20/ 80/80	< >
30	52	30		-	V 92564/30/ 52/30	< >	V 92567/30/ 52/30	< >
30	52	50		-	V 92564/30/ 52/50	< >	V 92567/30/ 52/50	< >
30	52	80		-	V 92564/30/ 52/80	< >	V 92567/30/ 52/80	< >
30	60	30		-	V 92564/30/ 60/30	< >	V 92567/30/ 60/30	< >
30	60	50		-	V 92564/30/ 60/50	< >	V 92567/30/ 60/50	< >
30	60	80		-	V 92564/30/ 60/80	< >		-
30	70	30		-	V 92564/30/ 70/30	< >	V 92567/30/ 70/30	< >
30	70	50		-	V 92564/30/ 70/50	< >	V 92567/30/ 70/50	< >
30	70	80		-		-	V 92567/30/ 70/80	< >
30	80	30		-	V 92564/30/ 80/30	< >	V 92567/30/ 80/30	< >
30	80	50		-	V 92564/30/ 80/50	< >	V 92567/30/ 80/50	< >
30	80	80		-	V 92564/30/ 80/80	< >	V 92567/30/ 80/80	< >
40	52	30	V 92561/40/ 52/30	< >	V 92564/40/ 52/30	< >	V 92567/40/ 52/30	< >
40	52	50	V 92561/40/ 52/50	< >	V 92564/40/ 52/50	< >	V 92567/40/ 52/50	< >
40	52	80	V 92561/40/ 52/80	< >	V 92564/40/ 52/80	< >	V 92567/40/ 52/80	< >
40	60	30		-	V 92564/40/ 60/30	< >	V 92567/40/ 60/30	< >
40	60	50	V 92561/40/ 60/50	< >	V 92564/40/ 60/50	< >	V 92567/40/ 60/50	< >
40	60	80	V 92561/40/ 60/80	< >	V 92564/40/ 60/80	< >	V 92567/40/ 60/80	< >
40	70	30		-	V 92564/40/ 70/30	< >	V 92567/40/ 70/30	< >
40	70	50		-	V 92564/40/ 70/50	< >	V 92567/40/ 70/50	< >
40	80	30	V 92561/40/ 80/30	< >	V 92564/40/ 80/30	< >	V 92567/40/ 80/30	< >
40	80	50	V 92561/40/ 80/50	< >	V 92564/40/ 80/50	< >	V 92567/40/ 80/50	< >
40	80	80	V 92561/40/ 80/80	< >	V 92564/40/ 80/80	< >	V 92567/40/ 80/80	< >
50	52	30	V 92561/50/ 52/30	< >	V 92564/50/ 52/30	< >	V 92567/50/ 52/30	< >
50	52	50	V 92561/50/ 52/50	< >	V 92564/50/ 52/50	< >	V 92567/50/ 52/50	< >
50	52	80	V 92561/50/ 52/80	< >	V 92564/50/ 52/80	< >	V 92567/50/ 52/80	< >
50	60	30		-	V 92564/50/ 60/30	< >	V 92567/50/ 60/30	< >

b1	l1	H	Q70	EUR	Q60	EUR	Q40	EUR
50	60	50	V 92561/50/ 60/50	< >	V 92564/50/ 60/50	< >	V 92567/50/ 60/50	< >
50	60	80	V 92561/50/ 60/80	< >	V 92564/50/ 60/80	< >	V 92567/50/ 60/80	< >
50	70	30		-	V 92564/50/ 70/30	< >	V 92567/50/ 70/30	< >
50	70	50		-	V 92564/50/ 70/50	< >	V 92567/50/ 70/50	< >
50	70	80		-	V 92564/50/ 70/80	< >		-
50	80	30	V 92561/50/ 80/30	< >	V 92564/50/ 80/30	< >	V 92567/50/ 80/30	< >
50	80	50	V 92561/50/ 80/50	< >	V 92564/50/ 80/50	< >	V 92567/50/ 80/50	< >
50	80	80		-	V 92564/50/ 80/80	< >	V 92567/50/ 80/80	< >
60	60	30	V 92561/60/ 60/30	< >	V 92564/60/ 60/30	< >	V 92567/60/ 60/30	< >
60	60	50	V 92561/60/ 60/50	< >	V 92564/60/ 60/50	< >	V 92567/60/ 60/50	< >
60	60	80	V 92561/60/ 60/80	< >	V 92564/60/ 60/80	< >	V 92567/60/ 60/80	< >
60	70	50		-	V 92564/60/ 70/50	< >		-
60	70	80		-	V 92564/60/ 70/80	< >		-
60	80	30		-	V 92564/60/ 80/30	< >	V 92567/60/ 80/30	< >
60	80	50	V 92561/60/ 80/50	< >	V 92564/60/ 80/50	< >	V 92567/60/ 80/50	< >
60	80	80	V 92561/60/ 80/80	< >	V 92564/60/ 80/80	< >	V 92567/60/ 80/80	< >
60	100	30		-	V 92564/60/100/30	< >	V 92567/60/100/30	< >
60	100	50	V 92561/60/100/50	< >	V 92564/60/100/50	< >	V 92567/60/100/50	< >
60	100	80	V 92561/60/100/80	< >	V 92564/60/100/80	< >	V 92567/60/100/80	< >
70	70	30		-	V 92564/70/ 70/30	< >	V 92567/70/ 70/30	< >
70	70	50		-	V 92564/70/ 70/50	< >	V 92567/70/ 70/50	< >
80	80	30		-	V 92564/80/ 80/30	< >	V 92567/80/ 80/30	< >
80	80	50		-	V 92564/80/ 80/50	< >	V 92567/80/ 80/50	< >
80	100	30		-	V 92564/80/100/30	< >	V 92567/80/100/30	< >
80	100	50		-	V 92564/80/100/50	< >	V 92567/80/100/50	< >
90	90	30		-	V 92564/90/ 90/30	< >		-
90	90	50		-	V 92564/90/ 90/50	< >	V 92567/90/ 90/50	< >
100	100	30		-	V 92564/100/100/30	< >	V 92567/100/100/30	< >
100	100	50		-	V 92564/100/100/50	< >	V 92567/100/100/50	< >

1) M6: ab b1=60 und l1=80 mit Gewindeinsatz