





PRODUCT DESCRIPTION

- » Loadable in any direction
- » Safety factor 4:1
- » Tool-free installation through captive key plate
- » All load-bearing parts are 100% crack tested and proof load tested according to EN 1677

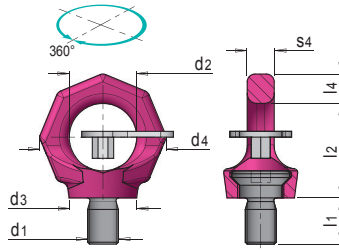

l1	l2	l4	d2	d3	d4	s4	d1	WLL				No.	EUR
								max. kg	max. kg	max. kg	max. kg		
9	28	9	20	23	37	7	M 6	500	100	200	140	E 1272/ 6	<>
12	35	11	25	25	47	9	M 8	1,000	300	600	420	E 1272/ 8	<>
15	35	11	25	25	47	9	M10	1,000	400	800	560	E 1272/10	<>
18	42	13	30	30	56	10	M12	2,000	750	1,500	1,000	E 1272/12	<>
24	49	15	35	36	65	13	M16	4,000	1,500	3,000	2,120	E 1272/16	<>
30	58	17	40	41	76	16	M20	6,000	2,300	4,600	3,220	E 1272/20	<>
36	70	20	49	51	92	19	M24	8,000	3,200	6,400	4,500	E 1272/24	<>
45	87	26	60	66	114	24	M30	12,000	4,500	9,000	6,300	E 1272/30	<>
54	103	32	72	76	135	29	M36	16,000	7,000	14,000	9,800	E 1272/36	<>
63	121	37	84	86	158	33	M42	24,000	9,000	18,000	12,600	E 1272/42	<>
72	138	42	94	100	180	42	M48	32,000	12,000	24,000	16,800	E 1272/48	<>

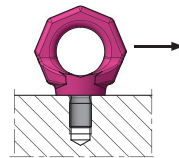

Do not rotate under load!

Rotate in the direction of force before loading!

Hand tighten, do not use extension!