
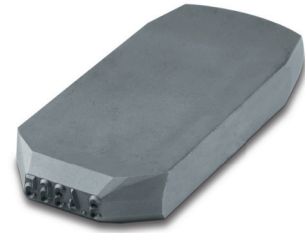


PRODUCT DESCRIPTION

- » Hardness of the engraving 58 - 60 HRC
- » For the marking of materials

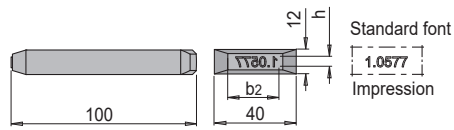

b2	h ¹⁾	Material name	No.	EUR
18	5	1.1730	V 28880/ 1730	< >
18	5	1.2083	V 28880/ 2083	< >
18	5	1.2085	V 28880/ 2085	< >
18	5	1.2162	V 28880/ 2162	< >
18	5	1.2311	V 28880/ 2311	< >
18	5	1.2312	V 28880/ 2312	< >
18	5	1.2316	V 28880/ 2316	< >
18	5	1.2343	V 28880/ 2343	< >
18	5	1.2344	V 28880/ 2344	< >
18	5	1.2363	V 28880/ 2363	< >
18	5	1.2379	V 28880/ 2379	< >
18	5	1.2714	V 28880/ 2714	< >

b2	h ¹⁾	Material name	No.	EUR
18	5	1.2767	V 28880/ 2767	< >
18	5	1.2842	V 28880/ 2842	< >
18	5	1.3343	V 28880/ 3343	< >
18	5	1.7131	V 28880/ 7131	< >
18	5	1.7225	V 28880/ 7225	< >
31	5	1.2083ESU	V 28880/ 2083ESU	< >
31	5	1.2343ESU	V 28880/ 2343ESU	< >
31	5	1.2344ESU	V 28880/ 2344ESU	< >
26	5	1.2714HH	V 28880/ 2714HH	< >
21	5	3.3547	V 28880/3.3547	< >
21	5	3.4365	V 28880/3.4365	< >

1) h: font size