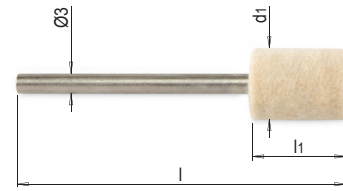

 
 

 







### DESCRIZIONE DEL PRODOTTO

- » Gambo Ø3 mm
- » Buona tenuta di forma



|    | Forma   |                | l    | d1 | l1 |  Pz. / UDC | N°                | EUR |
|----|---|----------------|------|----|----|--|-------------------|-----|
| A1 |    | Cilindro       | 48   | 6  | 10 | 10   | V 76704/ A1/ 6x10 | <>  |
|    |   |                | 48   | 8  | 10 | 10   | V 76704/ A1/ 8x10 | <>  |
|    |   |                | 52   | 10 | 14 | 10   | V 76704/ A1/10x14 | <>  |
|    |   |                | 50   | 12 | 20 | 10   | V 76704/ A1/12x20 | <>  |
| A3 |    | Cilindro tondo | 48   | 6  | 10 | 10   | V 76704/ A3/ 6x10 | <>  |
|    |   |                | 48   | 8  | 10 | 10   | V 76704/ A3/ 8x10 | <>  |
|    |   |                | 51   | 10 | 13 | 10   | V 76704/ A3/10x13 | <>  |
| C1 |    | Disco          | 46   | 21 | 4  | 10   | V 76704/ C1/21x4  | <>  |
| C3 |    | Lente          | 46   | 21 | 4  | 10   | V 76704/ C3/21x4  | <>  |
| E1 |   | Trapezio       | 51   | 8  | 13 | 10   | V 76704/ E1/ 8x13 | <>  |
|    |   |                | 53   | 10 | 15 | 10   | V 76704/ E1/10x15 | <>  |
|    |   |                | 55   | 15 | 15 | 10   | V 76704/ E1/15x15 | <>  |
| G1 |  | Cono           | 52   | 10 | 14 | 10   | V 76704/ G1/10x14 | <>  |
|    |   |                | 53   | 12 | 25 | 10   | V 76704/ G1/12x25 | <>  |
| G3 |  | Cono acuto     | 54   | 6  | 16 | 10   | V 76704/ G3/ 6x16 | <>  |
|    |   |                | 55   | 8  | 17 | 10   | V 76704/ G3/ 8x17 | <>  |
|    |   |                | 51,5 | 10 | 20 | 10   | V 76704/ G3/10x20 | <>  |
| J1 |  | Sfera          | 46   | 8  | -  | 10   | V 76704/ J1/ 8    | <>  |
|    |   |                | 48   | 10 | -  | 10   | V 76704/ J1/10    | <>  |
|    |   |                | 50   | 12 | -  | 10   | V 76704/ J1/12    | <>  |
| M4 |  | Goccia         | 56   | 12 | 18 | 10   | V 76704/ M4/12x18 | <>  |