



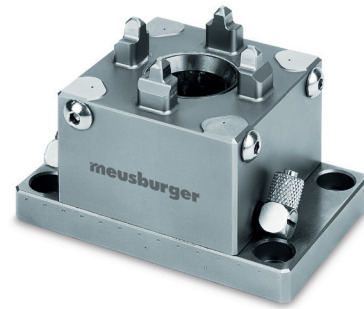

PRODUCT DESCRIPTION

- » Clamping with optimised set-up times
- » Operating pressure 6 bar
- » Corrosion-resistant with cleaning for Z axis
- » Clamping force max. 2800 N
- » Multiple clamping possible

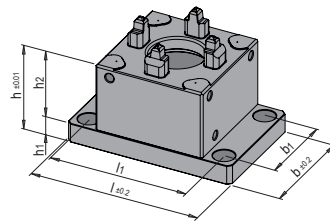

| b | b1 | l | l1 | h1 | h2 | h | Pcs./PU | No. | EUR |
|------|----|----|----|----|----|----|---------|---------------|-----|
| 55.6 | 40 | 85 | 70 | 10 | 35 | 45 | 1 | HER 3050/55,6 | < > |